



GROUP D

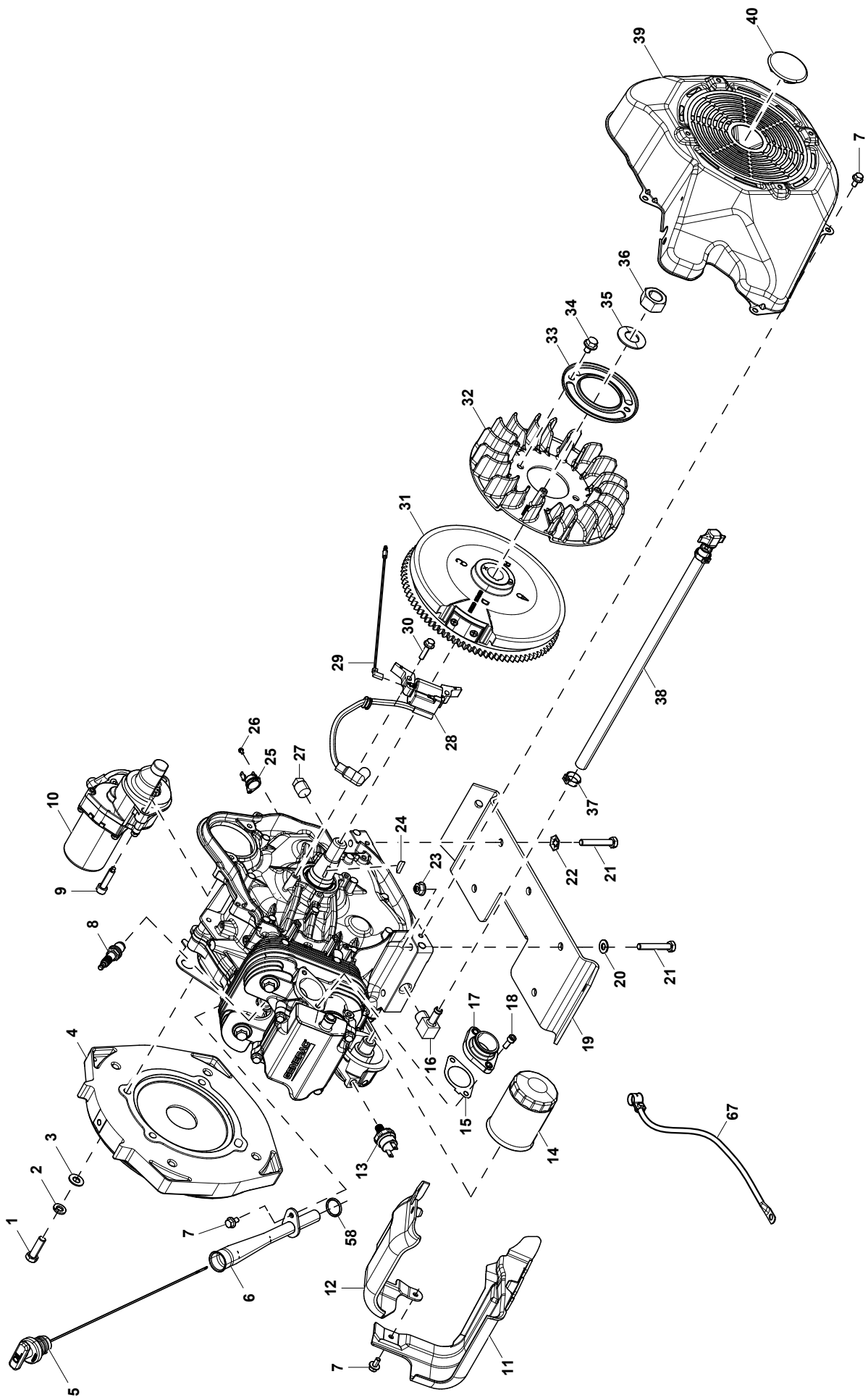

GROUP D

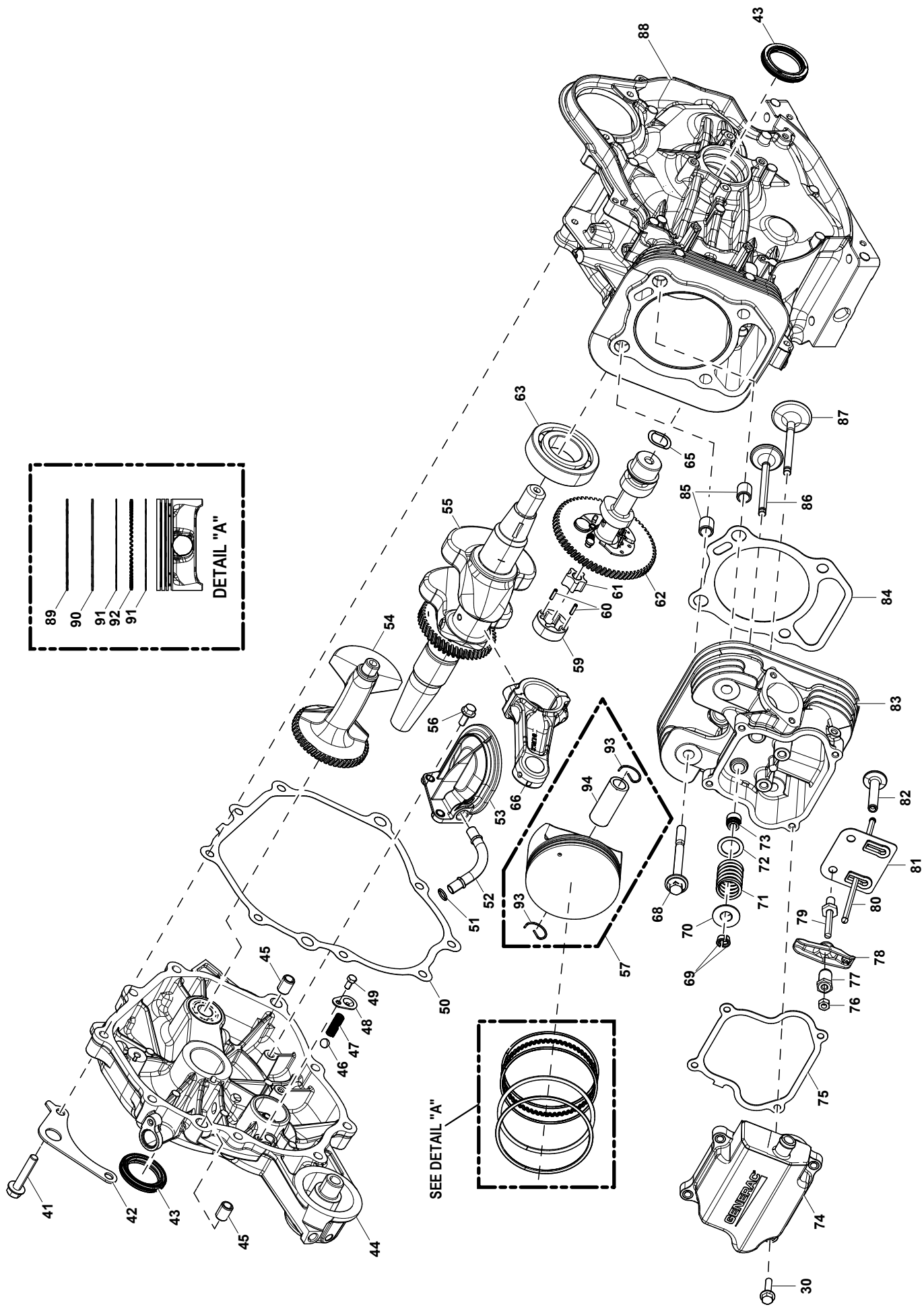

EXPLODEDVIEW: EV GH460 HSB 2019

DRAWING#: A0000347485

GROUP D

APPLICABLE TO:

ITEM	PART#	QTY.	DESCRIPTION
1	G022511	4	SCREW HHC 3/8-16 X 1-1/4 G5
2	G022237	4	WASHER LOCK SPRING 3/8 ZC
3	G022131	4	WASHER FLAT 3/8-M10 STEEL ZINC
4	0F8186	1	ADAPTOR ENGINE
5	10000001835	1	DIPSTICK GH426 ORANGE
6	0G1220	1	ASSY DIPSTICK TUBE CHECK/FILL
7	0C8563	9	SCREW HHFC M6-1.0 X 12 G8.8
8	0G0767B	1	SPARK PLUG GAP 0.020"
9	0L4322	2	DOGPOINT FASTENER M8-1.25 X 35
10	0L2040	1	ASSEMBLY STARTER MOTOR 426
11	0L3476	1	WRAPPER, HEAD LOWER GHS
12	0L3475	1	WRAPPER, HEAD UPPER GHS
13	0L2917B	1	LOW OIL PRES SWITCH 5 PSI NO
14	070185E	1	OIL FILTER 90 LOGO ORNG-CAN
15	0K9739	1	GASKET INT/ADAPT 426
16	10000006153	1	BARB EL SAE 3/8NPT X 3/8 ST-Z
17	0L3528	1	ADAPTOR INTAKE HSB GH 426
18	G064182	2	SCREW SHC M6-1.0 X 16 C12.9
19	0J8254AST03	1	410 ENG MOUNTING BRKT 2013 HSB
20	G022145	3	WASHER FLAT 5/16-M8 STEEL ZINC
21	G051731	4	SCREW HHC M8-1.25 X 50 C8.8
22	0C3168	1	WASHER LOCK SPECIAL 5/16
23	10000034692	4	NUT HEX FLANGE M8-1.25 LOCK NYLON
24	G082774	1	KEY, WOODRUFF 4 X 19D
25	10000024110	1	THERMAL SWITCH 310 F NC
26	0F2094	2	SCREW PPHMS M3-0.5 X 6
27	0D4788	1	PLUG STD PIPE 3/8 STEEL SQ HD
28	0L3498T	1	ASSY IGN COIL GH426 W/ ADVANCE
29	0K3166	1	ASSY WIRE #18 IGN COIL 2013
30	G080318	6	SCREW HHFC M6-1.0 X 25 FTH G8
31	A0000501999	1	FLYWHEEL ASSY 220MM 29 DEG
32	0E9486A	1	FAN, FLYWHEEL GT530, GLS FILLED
33	0C3032	1	PLATE, FAN GV-990
34	0K8288	2	SCREW HHFCS M8-1.25 X 12 C8.8
35	067198N	1	WASHER BELLEVILLE M20
36	G067890	1	NUT HEX M20-1.5 G8 YEL CHR
37	0G3662B	1	CLAMP HOSE STEPLESS 18.5
38	0H8131	1	ASSY HOSE OIL DRAIN 16" LG ORG
39	0K9112A	1	ASSY BLOWER HSG GH426 HSB
40	0L5419	1	BLWR HSG PLUG
41	0A1442	9	SCREW HHFC M8-1.25 X 42 G8.8
42	0L2777	1	BRACKET LIFTING HOOK
43	0E3812	2	SEAL D 35 X 48.2 VITON
44	0K9288A	1	ASSY GEAR COVER 426 W/BEARING
45	078699B	2	SLEEVE DOWEL PIN 12 DIA.
46	0A5776	1	BALL 11/32 DIA PRESSURE RELIEF
47	0A5771	1	SPRING, OIL RELIEF 360
48	G078691	1	COVER OIL PRESSURE RELIEF
49	G045770	1	SCREW HHC M5-0.8 X 10 C8.8
50	0K8944	1	GASKET CRANKCASE 426
51	0C3027	2	O-RING 3/8 X 1/2 NITRILE
52	0K8942	1	TUBE OIL PICKUP 426
53	0K8940	1	HOUSING, OIL PICKUP 426
54	0K7976	1	BALANCER SHAFT MACH 426
55	10000018815	1	ASSY CRANKSHAFT 69MM 1" SAE TAPER
56	G076340	2	SCREW HHFC M6-1.0 X 16 G8.8
57	10000017973	1	ASSY PISTON FLAT TOP 92 DIA
58	G097840	1	O-RING 15.6 X 19.16 X 1.78MM
59	G086002	1	GEROTOR, OUTER 12THK
60	G083222	2	PIN SPRING 3MM X 12MM
61	G086026	1	GEROTOR, INNER 12THK
62	0K8692	1	ASSY CAMSHAFT 426
63	0L0010	1	BEARING BALL 6207
64	10000017973	1	ASSY PISTON FLAT TOP 92 DIA
65	0B2104	1	WASHER, 3 WAVE

EXPLODEDVIEW: EV GH460 HSB 2019**DRAWING#: A0000347485****GROUP D****APPLICABLE TO:**

ITEM	PART#	QTY.	DESCRIPTION
66	10000016518	1	ASSY CONNECTING ROD 108.1MM
67	0J9420B	1	CABLE BATT BLK #6 30.0 NEG
68	10000023678	4	SCREW HWH SEMS M10-1.5 X 100
69	G086515	4	KEEPER,VLV SPRING
70	0D2274	2	RETAINER,VALVE SPRING
71	0D3867	2	SPRING VALVE GT-990
72	0C5371	2	WASHER VALVE SPRING
73	10000021593	2	VALVE STEM SEAL 6 X 12.7
74	0L3661B	1	ASSY ROCKER COVER GH426 OHVI
75	0K8946	1	GASKET ROCKER COVER 426
76	0K8145	2	NUT JAM ROCKER 426 LC168F
77	0K8144	2	BALL ROCKER ADJUSTING 426 LC168F
78	10000008511	2	ROCKER ARM
79	0K8143	2	STUD ROCKER 426 LC188F
80	0K8147	2	PUSH ROD 426
81	10000009646	1	PUSHROD GUIDE PLATE 5MM
82	G083897	2	TAPPET SOLID
83	10000011379	1	ASSY HEAD MACHINED 426
84	10000018030	1	GASKET HEAD 92MM
85	078699C	2	SLEEVE DOWEL PIN DIA.14
86	G086516	1	VALVE EXHAUST
87	0C2229	1	VALVE INTAKE
88	10000029018	1	ASSY CRANKCASE W/BEARING 92MM
89	10000017957	1	RING PISTON TOP DIA 92
90	10000017949	1	RING PISTON 2ND DIA 92
91	10000017991	2	RING PISTON OIL RAIL DIA 92
92	10000018000	1	RING PISTON OIL SPACER DIA 92
93	G071983	2	RETAINER PISTON PIN 20
94	0K6397	1	WRIST PIN 999 20X12X49