


GROUP

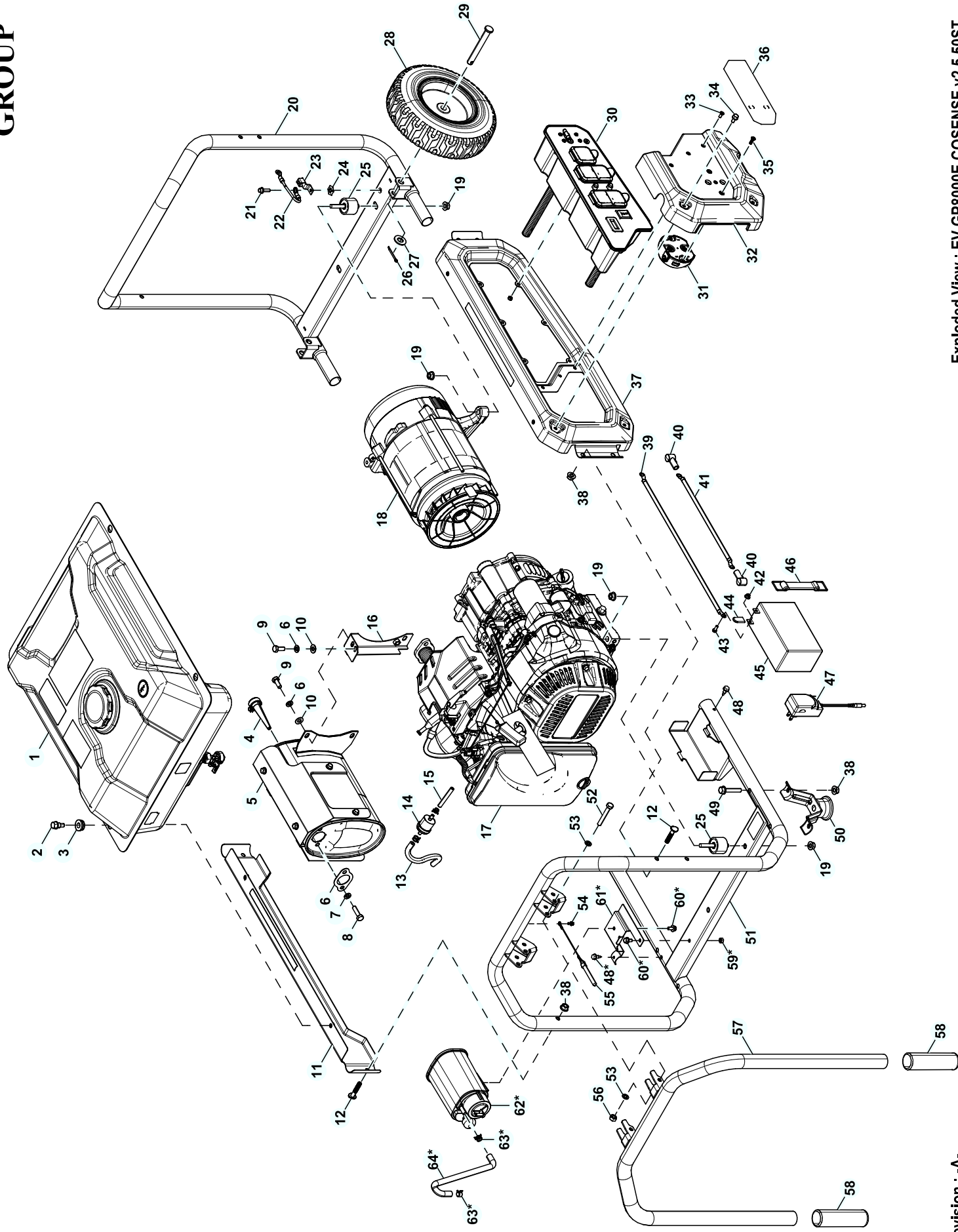

EXPLODEDVIEW: EV GP8000E COSENSE v2.5 50ST

DRAWING#: A0000769995

GROUP

APPLICABLE TO:

ITEM	PART#	QTY.	DESCRIPTION
1	10000031503	1	ASSEMBLY FUEL TANK 7.5 GAL GP
2	0G5445	4	SCREW HHTT M8-1.25 X 20
3	0H1411	4	RUBBER MOUNT, 10.8 ID X 9 TALL
4	0K3857	1	SPARK ARRESTOR ASSY USFS
5	10000041755	1	SSY MUFFLR GP 7.5KW
6	0G9028	1	GASKET, EXHAUST, 389CC
7	G022129	6	WASHER LOCK SPRING 5/16 ZC
8	G042909	2	SCREW HHC M8-1.25 X 30 C8.8
9	G039253	4	SCREW HHC M8-1.25 X 20 C8.8
10	022145	4	WASHER FLAT 5/16-M8 STEEL ZINC
11	10000031804	1	ST19 SIDE PANEL EXHAUST
12	0H1780	6	CURVED HEAD M8-1.25 X 42MM LNG
13	0G9757B	1	FUEL HOSE 4 ID X 8 OD X 80MM
14	0G9914	1	FUEL FILTER G19-389
15	0G9757A	1	FUEL HOSE 4 ID X 8 OD X 55MM
16	0G8542	1	BRACKET, MUFFLER 389CC
17	0H9838G	1	ENGINE 420 ES W/O MFLR EPACARB
18	0K0755	1	ALT 8000W ALUMINUM BRUSH TYPE
19	067989	8	NUT HEX FL WHIZ M8-1.25
20	10000031727	1	ST03 GP CRADLE ALTERNATOR HALF
21	0G3110	1	SCREW HHTT M6-1.0 X 20 ZINC
22	G0742600186	1	GROUND WIRE BRG CAR-LUG 4KW
23	G055414	1	LUG SLDLSS #2-#8 X 17/64 CU
24	0A1658	1	WASHER LOCK SPECIAL 1/4"
25	0H2043	4	VIB MOUNT 35 X 12 X M8-1.25
26	0D4999	2	PIN COTTER 1/8 X 1-1/4 ZN PLT
27	G022304	2	WASHER FLAT 1/2 STEEL ZINC
28	0K6011	2	WHEEL 9.5" DIA, PLASTIC
29	0H0204	2	AXLE PIN, 1/2"X 4", 3/4" HEAD
30	A0000592122	1	CONTROL PNL ASSY GP8 CO2.5
31	A0000267819	1	MODULE CO PORTGEN V2.5
32	10000030651	1	SHROUD SIDE PANEL CONTROL - GP80000E
33	0H1357	3	SCREW PFHM M5-0.8 X 12
34	G090388	2	SCREW HHTT M6-1.0 X 12 ZINC
35	10000031512	2	SCREW BHFH TORX M5.5-1.59 X 15
36	A0000657290	1	BADGE CO-SENSE V2.5 GP
37	A0000619545	1	ST19 WELDMENT SIDE PANEL V2.5
38	0J9125	10	NUT HEX FL WHIZ M8-1.25
39	0742600199	1	WIRE ASSY 8GA 17" BLACK
40	0G6392	2	BOOT VINYL STARTER-SOLENOID
41	0742600198	1	WIRE ASSY 8GA 11" RED
42	0H3535	4	NUT HEX FLANGE M5-0.8 LOCK NYLON
43	052618	2	SCREW HHC M5-0.8 X 12 C8.8
44	0K6009	1	BATTERY COVER HOT
45	0G9449	1	BATTERY 12V SEALED
46	0H7945	1	ASSEMBLY, BATTERY STRAP
47	10000020426	1	CHARGER AC ADAPTOR 14VDC PLUG
48	A0000211316	3	SCREW HHSD 1/4-14 X 3/4
49	0H1779	4	SCREW HHFC M8-1.25 X 45 G8.8
50	0K8933	2	FOOT ASSY GP
51	A0000621856	1	ST03 GP CRADLE ENGINE HALF
52	0J3317	2	SCREW HHC M8-1.25 X 55 PC8.8 BLK
53	0K3431	4	WASHER FLAT M8 NYLON
54	G045764	1	SCREW HHTT M4-0.7 X 8 ZP
55	0K3399	1	PIN QUICK RELEASE XT
56	G049820	2	NUT HEX LOCK M8-1.25 NY INS
57	A0000683482	1	ST03 WELDMENT HANDLE GP
58	10000031500	2	HANDLE GRIP GP
59*	0B2236	1	NUT HEX LOCK M6-1 NY INS
60*	0C8563	2	SCREW HHFC M6-1.0 X 12 G8.8
61*	0K3512	1	CARB CAN CRADLE BRACKET XT
62*	0H0957	1	CARBON CANISTER
63*	048031C	2	CLAMP HOSE BAND .50
64*	0K3567	1	HOSE FORMED 13 OD X 8 ID X 278