

GP9500E TF

GP SERIES Portable Generator

Model 8061-0 UPC: 696471103762
(50-State)

Features


- **Tri Fuel** – Runs on Gasoline, Liquid Propane and Natural Gas Fuel for your convenience.
- **10.5-Hour Runtime** when running on gasoline and 5-Hour Runtime on 20lb LP tank when 50% of power is being used.
- **Easy-to-Use Electric Start** – Rocker switch provides reliable and hassle-free start-ups with Auto Choke (Battery included).
- **Efficient OHV Engine** – 500cc OHV engine with EFI technology optimizes fuel efficiency and requires less maintenance.
- **Handle & Wheel Kit** – Ergonomic handle and never-flat wheel kit included for portability.
- **1 ¼" steel-tube cradle** for added durability and strength.
- **Covered outlets** provide added protection from the environment and rugged working conditions.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **HomeLink™ Manual Transfer Switch compatible** designed to work with HomeLink™ manual transfer switches for safe home backup power.

*Increases electrical current upon demand above rated output when starting electric motors.



Running Watts / Starting Watts
9500 / 12500 (Gas)
8550 / 11250 (Propane)
7000 / 9000 (Natural Gas)

Control Panel

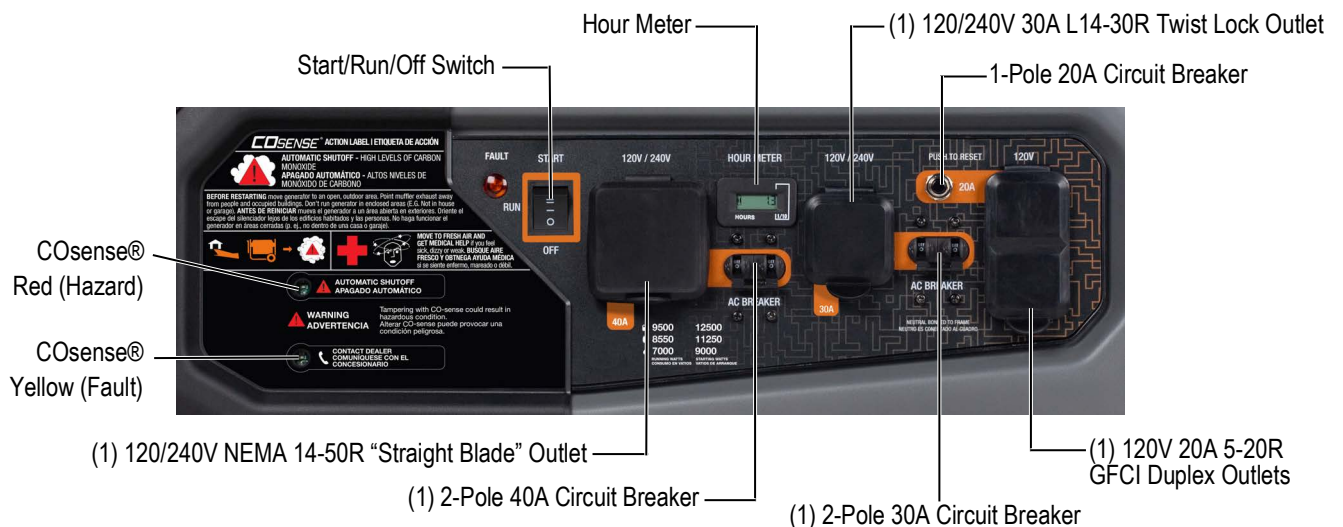

GP9500E TF

Specifications

Product Series	GP9500E TF
Model Number	8061-0
Configuration	50-State (CARB 2024)
AC Rated Output Running Watts	9500 (Gas) / 8550 (LP) / 7000 (NG)
AC Maximum Output Starting Watts	12500 (Gas) / 11250 (LP) / 9000 (NG)
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	79.2 / 39.6
Engine Displacement	500cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	1.06 (1.0)
Lubrication Method	Splash
Automatic Voltage Regulation (AVR)	Yes
Choke Location	Auto Choke (EFI)
Fuel Shut Off	On Fuel Tank
Starting Method	Electric Start / Recoil Pull Start

Battery Included	Yes
Battery Type	Lead Acid (12V DC, 9Ah)
Battery Part No.	A0006353770
Battery Dimensions	5.94" x 2.56" x 3.70"
Low Oil Shutdown	Yes
Neutral Bonded to Ground	Yes
Start Switch Type	Off/Run/Start
Start Switch Location	On Control Panel
Fuel Gauge	Yes
Fuel Tank Capacity gal (L)	7.5 (28.4)
Run Time at 25% (Hours)	13 (Gas) 6.5 (LP)
Run Time at 50% (Hours)	10.5 (Gas) 5 (LP)
Handle Style	Dual Grip, Single Folding with Lock Pin
Wheel Type	9.5" Never Flat
Warranty- Residential	3 Year Limited
Warranty- Commercial	2 Year Limited
Included	Engine oil, handle & wheel kit, battery, owner's manual, LP hose with primary regulator to connect 20lb LP tank

Dimensions and Weights

Length in (mm)	27.2 (692)
Width in (mm)	26.94 (684.4)
Height in (mm)	27 (703)
Extended Length in (mm)	44.9 (1141)
Carton Length in (mm)	28.5 (725)
Carton Width in (mm)	21.7 (550)
Carton Height in (mm)	29.1 (740)
Unit Weight lbs (kg)	227 (103)
Shipping Weight lbs (kg)	244 (110.5)

