

GP8000E

GP SERIES Portable Generator

1 of 2

Model G008929-0 UPC: 696471104172
(50-State)


Features

- **12-Hour Runtime** when running on gasoline and 50% of power is being used.
- **Easy-to-Use Electric Start** – Rocker switch provides reliable and hassle-free start ups (Battery included).
- **Fuel-Efficient OHV Engine** – 420cc OHV engine with EFI technology optimizes fuel efficiency and requires less maintenance.
- **Handle & Wheel Kit** – Ergonomic handle and never-flat wheel kit included for portability.
- **1 1/4" steel-tube cradle** for added durability and strength.
- **Covered outlets** provide added protection from the environment and rugged working conditions.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **HomeLink™ Manual Transfer Switch compatible** designed to work with HomeLink™ manual transfer switches for safe home backup power.



Running Watts 8000
Starting Watts 10000

Control Panel

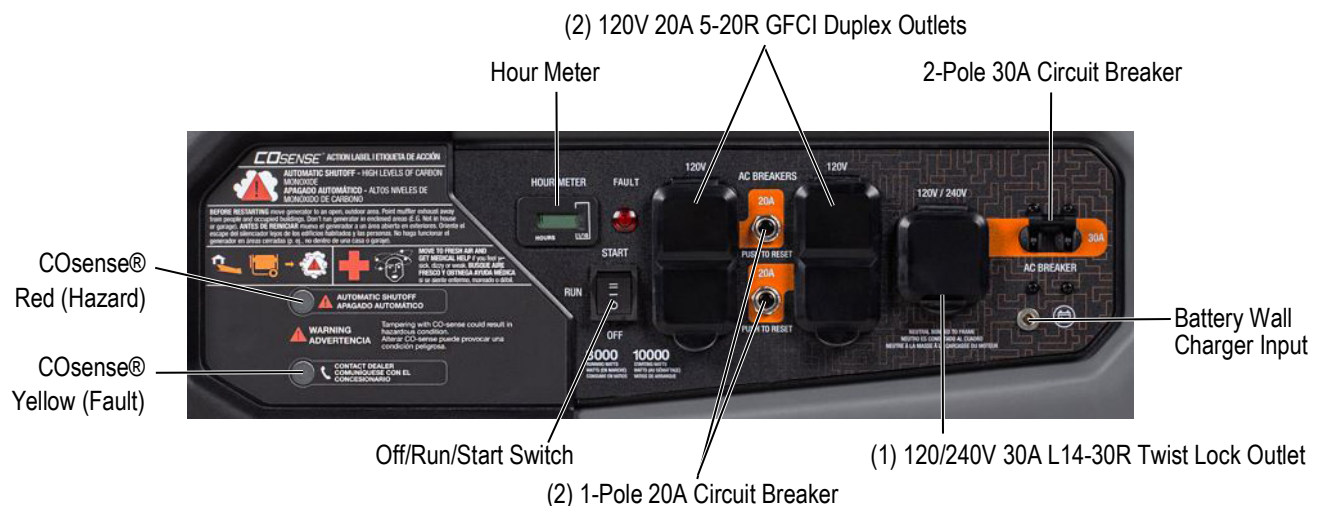

GP8000E

Specifications

Product Series	GP8000E
Model Number	8929-0
Configuration	50-State
AC Rated Output Running Watts	8000
AC Maximum Output Starting Watts	10000
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	66.6/33.3
Engine Displacement	420cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	1.06 (1.0)
Lubrication Method	Splash
Automatic Voltage Regulation (AVR)	Yes
Starting Method	Electric Start / Recoil Pull Start
Battery Included	Yes
Battery Type	Lead Acid (12V DC, 9Ah)

Battery Part No.	A0006353770
Battery Dimensions	5.94" x 2.56" x 3.70"
Battery Wall Charger Adapter	Included
Low Oil Shutdown	Yes
Neutral Bonded to Ground	Yes
Start Switch Type	Off/Run/Start
Start Switch Location	On Control Panel
Fuel Gauge	Yes
Fuel Tank Capacity gal (L)	7.9 (29.9)
Run Time at 25% (Hours)	15.5
Run Time at 50% (Hours)	12
Handle Style	Dual Grip, Single Folding with Lock Pin
Wheel Type	9.5" Never Flat
Warranty- Residential	3 Year Limited
Warranty- Commercial	2 Year Limited
Included	Engine oil, handle & wheel kit, battery & charger, owner's manual

Dimensions and Weights

Length in (mm)	30.2 (767.8)
Width in (mm)	27.2 (691)
Height in (mm)	26.5 (672.6)
Extended Length in (mm)	44.9 (1140.9)
Carton Length in (mm)	28.3 (720)
Carton Width in (mm)	21.7 (550)
Carton Height in (mm)	28 (710)
Unit Weight lbs (kg)	207 (93.3)
Shipping Weight lbs (kg)	220 (99.8)

